


GPX 16 Ø16 mm, planetary gearbox

GPX




Key Data		LN Noise Reduced	LZ Backlash Reduced
Max. transmittable power	W	5.2	3.2
Max. continuous torque	Nm	0.36	0.5
Max. continuous input speed	rpm	16000	16000
Ambient temperature	°C	-40 ... +85	-40 ... +100
Bearing at output		Ball bearing	Ball bearing
Typical noise level	dBA	-5 dBA compared to standard configuration	

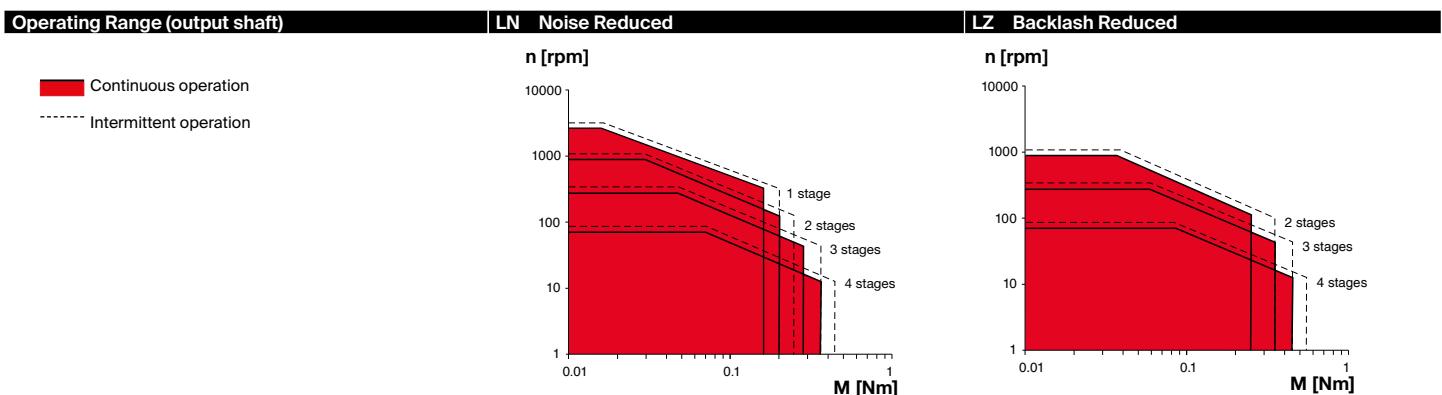

Specifications	LN	Noise Reduced	2	3	4	LZ	Backlash Reduced	2	3	4
Number of stages		1	2	3	4			2	3	4
Max. transmittable continuous power	W	5.2	2.6	1.3	0.5			3.2	1.6	0.6
Max. transmittable intermittent power	W	6.5	3.3	1.6	0.6			4.0	2.0	0.8
Max. continuous torque	Nm	0.16	0.20	0.28	0.36			0.25	0.35	0.45
Max. intermittent torque	Nm	0.20	0.25	0.35	0.45			0.35	0.45	0.55
Max. continuous input speed	rpm	12000	14000	16000	16000			14000	16000	16000
Max. intermittent input speed	rpm	15000	17500	20000	20000			17500	20000	20000
Max. efficiency	%	90	80	75	65			80	75	65
Average backlash no load	°	1.0	1.2	1.3	1.4			0.8	0.9	1.0
Max. axial load (dynamic)	N	20	20	20	20			20	20	20
Max. radial load, 5 mm from flange	N	30	45	70	70			45	70	70
Gearhead length L1 ¹	mm	15.8	20.7	25.7	30.6			20.7	25.7	30.6
Weight	g	20	25	27	30.6			25	27	30.6

Configuration	LN	Noise Reduced	2	3	4	LZ	Backlash Reduced	2	3	4
Number of stages		1	2	3	4			2	3	4
Reduction	X:1	3.9, 5.3, 6.6	16, 21, 26,	62, 83, 103,	243, 326, 406,			16, 21, 26,	62, 83, 103,	243, 326, 406,
Absolute reduction: (see online)			28, 35, 44	111, 138, 150,	439, 546, 590,			28, 35, 44	111, 138, 150,	439, 546, 590,
				172, 186, 231	679, 734, 794,				172, 186, 231	679, 734, 794,
					913, 987, 1135,					913, 987, 1135,
					1227, 1526					1227, 1526
Version		Standard/ceramic version/noise reduced/backlash reduced/high power								
Flange		Standard flange/configurable flange								
Shaft		Length/flat face								

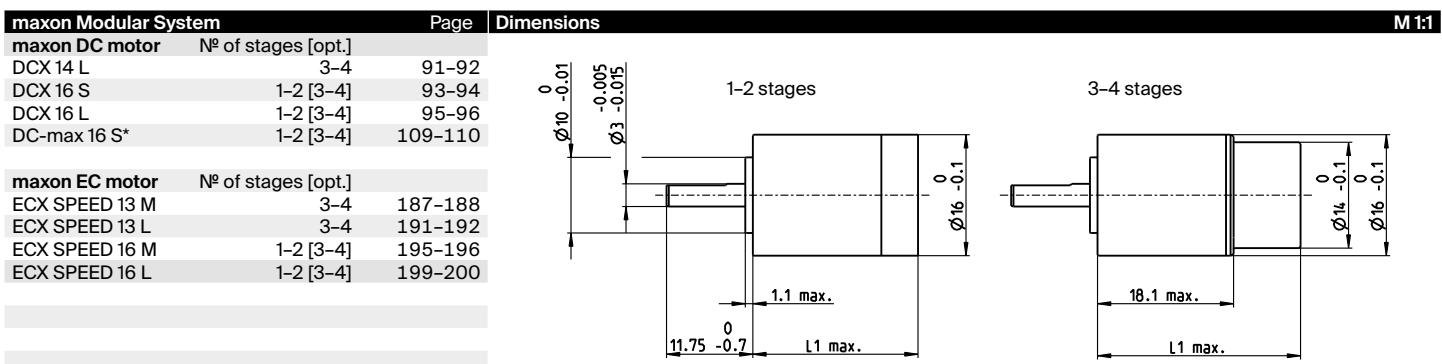

*Limited selection of reduction ratios
(see online).

¹This length may vary depending on the configuration and choice of motor. The effective length is calculated at the end of the configuration process.

gpx.maxongroup.com